


FOR OUTDOOR

MAINTENANCE WORK

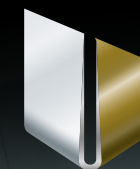

**HALDER**



german  
brand  
award  
19  
gold



**SUPERCRAFT SLEDGE  
SERIES 3366.VS**

- Non-rebound, high impact
- Safe alternative to hitting steel on steel
- Vibration-reducing Hickory handle
- Replaceable inserts made of hard extruded nylon: **No chipping** (even at temperatures below zero), will not crack

Art. No.	∅ [in]	[oz]	[in]
3366.081	3.15	155.56	34.65
3366.107	3.94	248.68	39.37
3366.110	3.94	328.05	39.37



**SUPERCRAFT SERIES 3377.1**

- Non-rebound, high impact
- Safe alternative to hitting steel on steel
- Break-proof steel tube handle and fluorescent yellow powder coating
- Replaceable inserts made of hard extruded nylon: **No chipping** (even at temperatures below zero), will not crack

Art. No.	∅ [in]	[oz]	[in]
3377.140	1.57	28.40	12.01
3377.150	1.97	40.57	12.40
3377.160	2.36	61.73	12.80

**HALDER**  
USA

**HALDER, INC.**

821 W College Ave  
Waukesha, WI 53186

 
www.halderusa.com  
sales@halderusa.com  
(888) 395-0168

**MALLET BLOCK**

- Hit it: That fits
- For road, walkway and park construction
- Durable, heavy-duty special plastic
- To offset any differences in height

Art. No.	[in]	[in]	[in]	[oz]
3688.001	7.87	5.51	1.57	37.57

Distributed by:



GB/USA/05/2020



103.142



**THE  
ORIGINAL  
FOR PROFESSIONALS**

**CONSTRUCTION / LANDSCAPING  
AND HARDSCAPING**

## PAVER INSTALLATION



## FLOOR TILING / NATURAL STONE SETTING



## FLOOR TILING / PAVING OF DELICATE MATERIAL



### SIMPLEX SERIES 3027

- All parts are replaceable
- High quality wood handle
- Robust and extremely durable cast iron housing
- 2 different inserts: Rubber composition (black, medium hard, impact cushioning, odorless, low-wear hardness) / Superplastic (white, medium hard, very durable, wear-resistant)

Art. No.	∅ [in]	[oz]	[in]
3027.050	1.97	38.98	14.57
3027.060	2.36	53.26	15.94
3027.080	3.15	97.71	19.29

### SLEDGE HAMMER

#### SIMPLEX SERIES 3027.VS

- All parts are replaceable
- High quality Hickory handle, high density, long-stranded, very robust
- Robust and extremely durable cast iron housing
- 2 different inserts: Rubber composition (black, medium hard, impact cushioning, odorless, low-wear hardness) / Superplastic (white, medium hard, very durable, wear-resistant)

Art. No.	∅ [in]	[oz]	[in]
3027.081	3.15	111.82	31.50
3027.100	3.94	188.72	39.37

### SIMPLEX SERIES 3013

- All parts are replaceable
- High quality wood handle
- Robust and extremely durable cast iron housing
- 2 different inserts: TPE-soft (blue, soft, **non-marring**) / TPE-mid (grey, medium hard, **non-marring**)

Art. No.	∅ [in]	[oz]	[in]
3013.050	1.97	37.39	14.57
3013.060	2.36	50.09	15.94

### SIMPLEX SERIES 3012

- All parts are replaceable
- High quality wood handle
- Robust and extremely durable cast iron housing
- 2 different inserts: TPE-soft (blue, soft, **non-marring**) / Rubber composition (black, medium hard, impact cushioning, odorless, low-wear hardness)

Art. No.	∅ [in]	[oz]	[in]
3012.050	1.97	38.62	14.57
3012.060	2.36	52.21	15.94

### SIMPLEX SERIES 3113

- **Extremely lightweight aluminium housing**
- All parts are replaceable
- High quality wood handle
- 2 different inserts: TPE-soft (blue, soft, **non-marring**) / TPE-mid (grey, medium hard, **non-marring**)

Art. No.	∅ [in]	[oz]	[in]
3113.050	1.97	22.40	14.57
3113.060	2.36	29.98	15.94

### SIMPLEX SERIES 3137

- **Extremely lightweight aluminium housing**
- All parts are replaceable
- High quality wood handle
- 2 different inserts: TPE-mid (grey, medium hard, **non-marring**) / Superplastic (white, medium hard, very durable, wear-resistant)

Art. No.	∅ [in]	[oz]	[in]
3137.050	1.97	22.76	14.57
3137.060	2.36	30.88	15.94