


## THE SPECIALIST FOR PRECISE AND GENTLE WORK




## LOCKSMITH'S HAMMER REDUCED REBOUND



**HALDER**

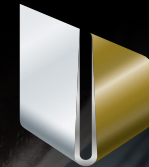

german  
brand  
award  
19  
gold

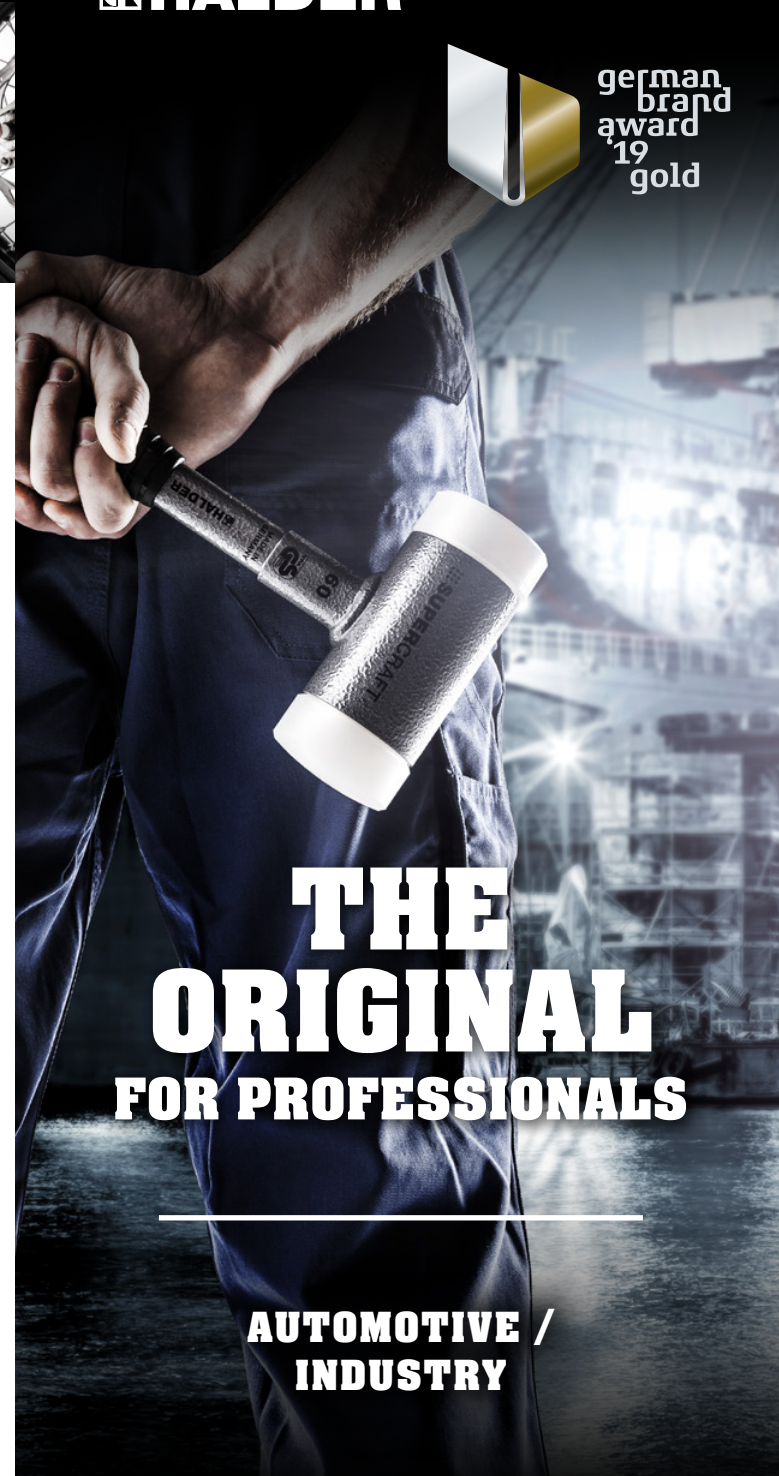

**THE ORIGINAL FOR PROFESSIONALS**

**AUTOMOTIVE / INDUSTRY**

### PUNCHES/DROP-MALLETS



- The little helpers for maintenance in an environment of limited accessibility
- Dead Blow – Ø 0.79 / 1.18 / 1.57 / 1.97 inch
- Replaceable inserts made of hard extruded nylon: **No chipping** (even at temperatures below zero), will not crack
- Replaces Brass Tip Drift Punches

Art. No.	Ø [in]	oz [oz]	Length [in]
3408.010	0.39	3.17	6.61
3408.012	0.47	4.59	6.69
3408.015	0.59	7.05	6.89
3408.020	0.79	7.58	5.91
3408.030	1.18	16.58	6.10
3408.040	1.57	27.69	6.30
3408.050	1.97	44.09	6.50

### MAXXCRAFT SERIES 3666



- Noticeable reduced rebound and thus full transmission of the power of impact onto the workpiece, caused by patented rubber connection between head and handle
- Reduced rebound (minus 69%)
- Higher impact (plus 24%)
- Protective handle sleeve with rubber coating
- According to DIN 1041

Art. No.	oz [oz]	Length [in]
3666.003	10.58	11.81
3666.005	17.64	12.60
3666.008	28.22	13.78
3666.010	35.27	14.17

 
**HALDER**  
USA

**HALDER, INC.**

821 W College Ave  
Waukesha, WI 53186

www.halderusa.com  
sales@halderusa.com  
(888) 395-0168

Distributed by:



GB/USA/09/2020



103.149

### SECURAL SERIES 3380

- The specialist for corners and edges
- **Maximum rebound damping**
- Absolutely unbreakable connection
- Interchangeable inserts made of polyurethane: rectangular, medium-hard, noise-dampening, impact cushioning, wear-resistant

Art. No.	Length x Width [in]	oz [oz]	Length [in]
3380.040	1.18 x 1.57	23.99	11.81
3380.045	1.37 x 1.77	35.28	12.20



## ASSEMBLY / REPAIR / MAINTENANCE WORK



## STRAIGHTENING WORK / WHEEL CHANGE

## POSITIONING AND ADJUSTING OF WORKPIECES

### SIMPLEX SERIES 3749

- All parts are replaceable
- **High impact strength** (due to additional increase in weight)
- **High stability** (reinforced cast iron housing, fibre-glass handle)
- Replaces conventional copper and lead mallets
- 2 different inserts: Copper (hard) / Soft metal (silver, hard, heat-resistant)

Art. No.	Ø [in]	Weight [oz]	Length [in]
3749.030	1.18	20.81	11.81
3749.040	1.57	42.15	12.99

### SIMPLEX SERIES 3028

- All parts are replaceable
- High quality wood handle
- Robust and extremely durable cast iron housing
- 2 different inserts: Rubber composition (black, medium hard, impact cushioning, odorless, low-wear hardness) / Nylon (white, hard, very wear-resistant, **no chipping**, oil and grease resistant)

Art. No.	Ø [in]	Weight [oz]	Length [in]
3028.030	1.18	12.52	11.61
3028.040	1.57	22.93	12.80
3028.050	1.97	40.21	14.57
3028.060	2.36	53.62	15.94
3028.080	3.15	101.94	19.29

### DEAD BLOW SLEDGE HAMMER SUPERCRAFT SERIES 3366.VS

- **Non-rebound, high impact**
- Vibration-reducing hickory handle
- No mushrooming or shrapnel when hitting steel stakes or pins
- Replaceable inserts made of hard extruded nylon: **No chipping** (even at temperatures below zero), will not crack

Art. No.	Ø [in]	Weight [oz]	Length [in]
3366.081	3.15	155.56	34.65
3366.100	3.94	248.68	39.37
3366.107	3.94	328.05	39.37

### BLACKCRAFT SERIES 3379

- **Non-rebound, high impact**
- Fully sheathed with polyurethane
- Prevents scratches as well as sparking in case of failures
- Completely robot welded
- With ergonomic, anti-slip and break-proof steel tube handle

Art. No.	Ø [in]	Weight [oz]	Length [in]
3379.040	1.57	22.58	11.81
3379.050	1.97	31.75	12.20
3379.060	2.36	45.86	12.40

### SUPERCRAFT SERIES 3389

- **Non-rebound, high impact**
- Ergonomic, anti-slip and break-proof three-component handle
- Replaceable inserts made of hard extruded nylon: **No chipping** (even at temperatures below zero), will not crack

Art. No.	Ø [in]	Weight [oz]	Length [in]
3389.040	1.57	27.87	14.57
3389.050	1.97	36.68	14.96
3389.060	2.36	57.32	15.35

### SUPERCRAFT SERIES 3377

- **Non-rebound, high impact**
- Break-proof steel tube handle and ergonomic, anti-slip grip
- Replaceable inserts made of hard extruded nylon: **No chipping** (even at temperatures below zero), will not crack

Art. No.	Ø [in]	Weight [oz]	Length [in]
3377.025	0.98	13.58	10.63
3377.030	1.18	20.64	11.61
3377.040	1.57	28.40	12.01
3377.050	1.97	40.57	12.40
3377.060	2.36	61.73	12.80
3377.070	2.76	79.37	13.19