


## V-Blocks

EH 1048.500 - EH 1148.500

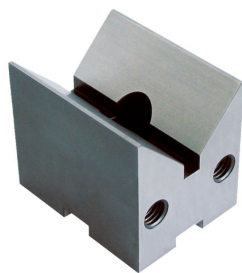


### Product Description

#### Material

- Steel, case-hardened, ground

### Drawing

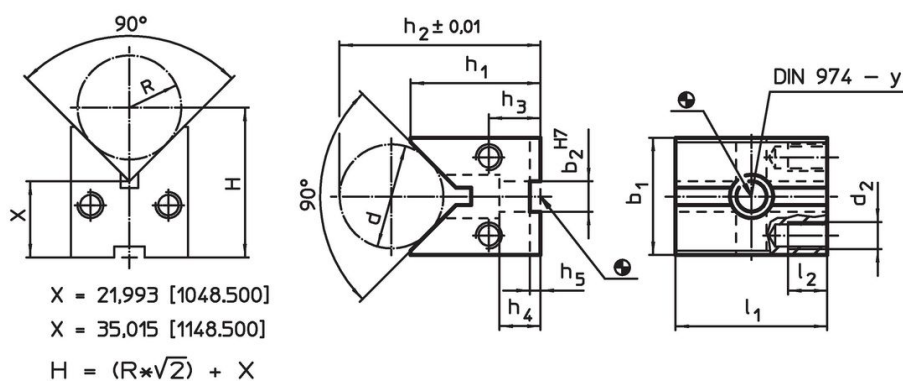

### Order information

System	Dimensions													For screws	y	📦	Art. No.
	$l_1$	$b_1$	$b_2$	$h_1$	$h_2$	$h_3$	$h_4$	$h_5$	$l_2$	$d$	$d_2$	d min.	d max.				
V40	40	32	10	36	48.55	14.5	13	2.6	10	22	M 8	8	35	M 6	6	262	1048.500
V70	70	54	14	60	83.30	24.0	19	5.0	18	40	M12	12	67	M12	12	1251	1148.500

### Compliance

#### RoHS compliant

Compliant according to Directive 2011/65/EU and Directive 2015/863.

#### Does not contain SVHC substances

No SVHC substances with more than 0.1% w/w contained - SVHC list [REACH] as of 23.01.2024.

#### Does not contain Proposition 65 substances

No Proposition 65 substances included.

<https://www.P65Warnings.ca.gov/>

#### Free from Conflict Minerals

This product does not contain any substances designated as "conflict minerals" such as tantalum, tin, gold or tungsten from the Democratic Republic of Congo or adjacent countries.