

## Positioning Clamping Bars • two-sided

EH 1049.200 - EH 1149.200




### Product Description


#### Material

- Steel, case-hardened, ground

### Drawing

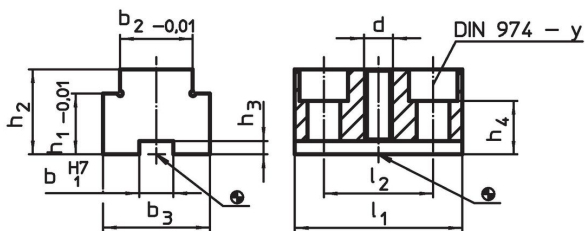

### Order information

System	Dimensions										y [mm]	For screws [mm]	 [g]	Art. No.
	b <sub>1</sub>	b <sub>2</sub>	b <sub>3</sub>	h <sub>1</sub>	h <sub>2</sub>	h <sub>3</sub>	h <sub>4</sub>	l <sub>1</sub>	l <sub>2</sub>	d				
V40	10	20	28	20	23	2.6	13	40	26	M 8	6	M 6	160	1049.200
V70	14	30	44	25	35	5.5	22	69	45	M12	12	M12	580	1149.200

### Compliance

#### RoHS compliant

Compliant according to Directive 2011/65/EU and Directive 2015/863.

#### Does not contain SVHC substances

No SVHC substances with more than 0.1% w/w contained - SVHC list [REACH] as of 27.06.2024.

#### Does not contain Proposition 65 substances

No Proposition 65 substances included.

<https://www.P65Warnings.ca.gov/>

#### Free from Conflict Minerals

This product does not contain any substances designated as "conflict minerals" such as tantalum, tin, gold or tungsten from the Democratic Republic of Congo or adjacent countries.