

Base Plates

EH 1500.200 - EH 1600.900



Product Description

Material


- Grey cast iron, ground

More information

Notes

Customized design on request.

Drawing

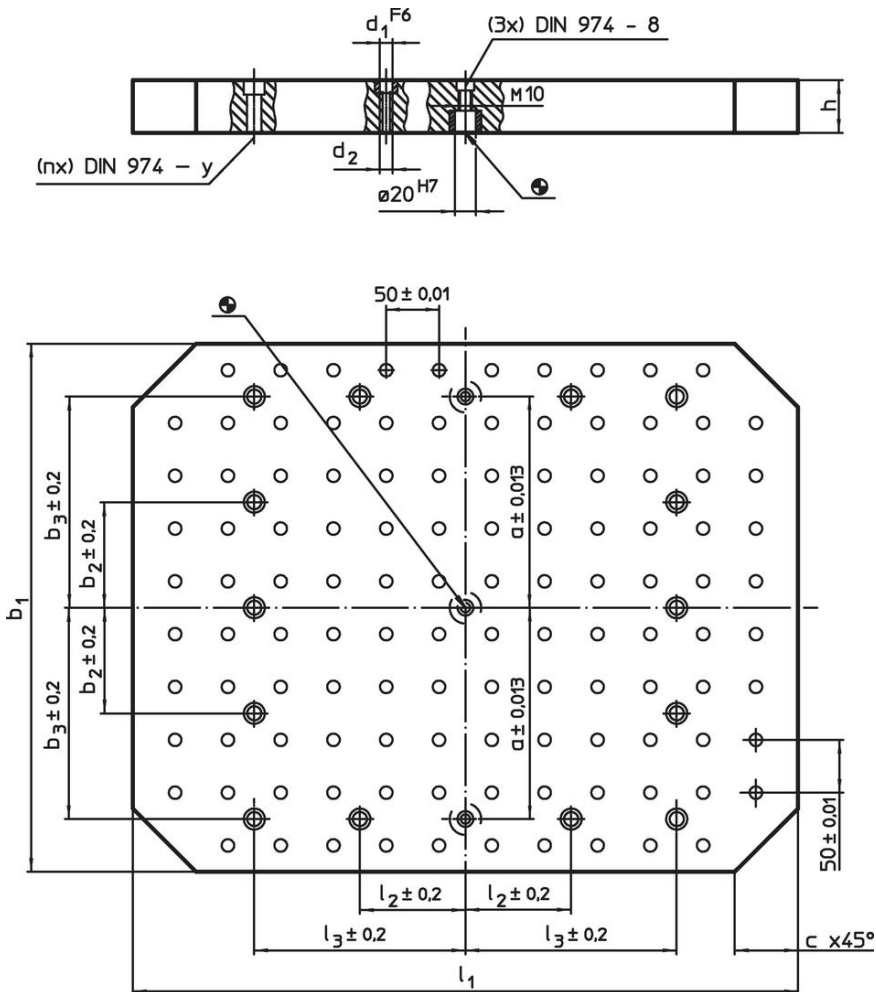

Order information

System	$b_1 \times l_1$	h	Dimensions								y	For screws	Number of fastening holes n	Number of hole rows	[kg]	Art. No.
			d_1	d_2	a	b_2	b_3	c	l_2	l_3						
[mm]																
L12	400 x 400	40±0.02	12	M12	150	-	150	50	-	100	12	M12	4	8 x 8	43	1500.200
L12	400 x 500	40±0.02	12	M12	150	-	150	50	-	200	12	M12	4	8 x 10	56	1500.300
L12	500 x 500	40±0.02	12	M12	200	100	200	60	100	200	12	M12	8	10 x 10	65	1500.400
L12	500 x 630	50±0.03	12	M12	200	100	200	60	100	200	12	M12	8	10 x 12	105	1500.500
L12	630 x 630	50±0.03	12	M12	200	-	200	70	-	200	16	M16	6	12 x 12	132	1500.600
L16	630 x 630	50±0.03	16	M16	200	-	200	70	-	200	16	M16	6	12 x 12	131	1600.600
L16	630 x 800	50±0.03	16	M16	200	-	200	70	-	300	16	M16	6	12 x 16	170	1600.700
L16	800 x 800	50±0.03	16	M16	300	100	300	100	100	300	16	M16	12	16 x 16	205	1600.800
L16	800 x 1000	60±0.03	16	M16	300	100	300	100	100	400	16	M16	12	16 x 20	325	1600.900

Application example







Compliance

RoHS compliant

Compliant according to Directive 2011/65/EU and Directive 2015/863.

Does not contain SVHC substances

No SVHC substances with more than 0.1% w/w contained - SVHC list [REACH] as of 27.06.2024.

Does not contain Proposition 65 substances

No Proposition 65 substances included.

<https://www.P65Warnings.ca.gov/>

Free from Conflict Minerals

This product does not contain any substances designated as "conflict minerals" such as tantalum, tin, gold or tungsten from the Democratic Republic of Congo or adjacent countries.