

Stops · plain  
EH 1586.



Product Description

Material


Inserts

- Hard metal

Body

- Tool steel, hardened

Drawing

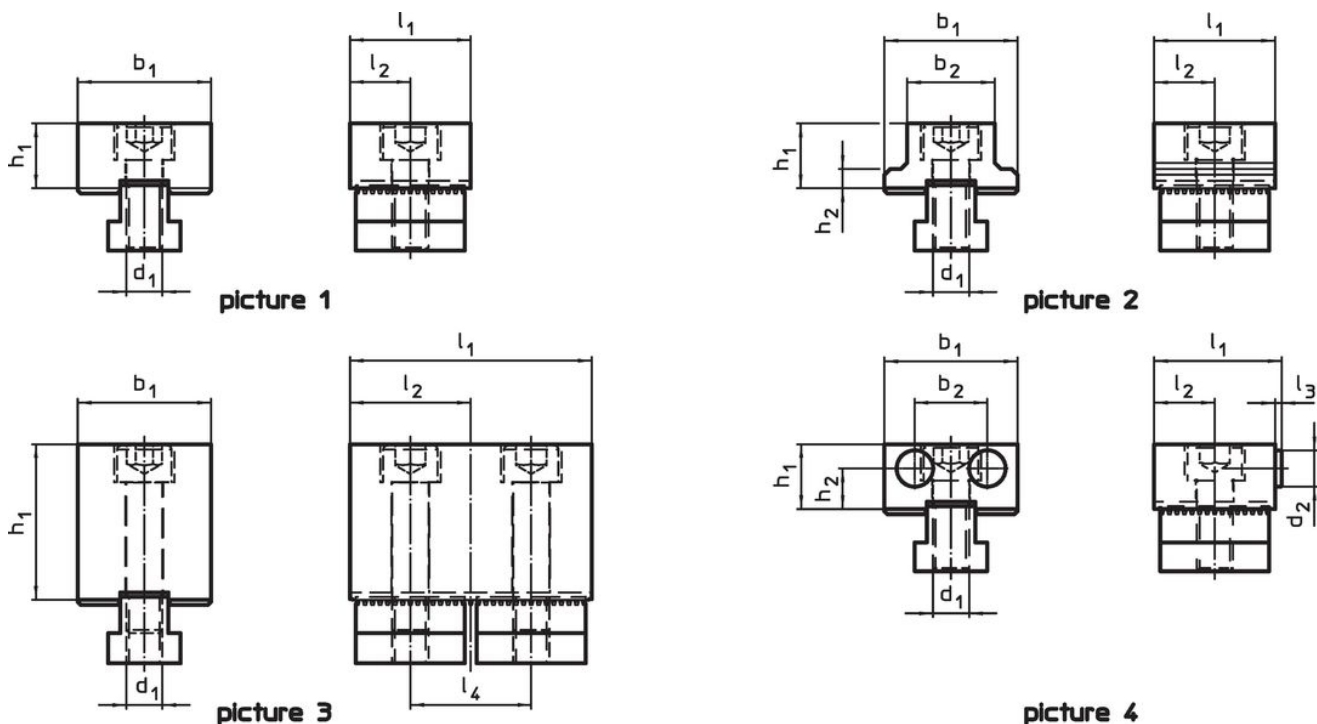

Order information

d <sub>1</sub>	d <sub>2</sub>	l <sub>1</sub>	Dimensions				b <sub>1</sub>	b <sub>2</sub>	h <sub>1</sub>	h <sub>2</sub>	[g]	Art. No.
			l <sub>2</sub>	l <sub>3</sub>	l <sub>4</sub>	[mm]						
<b>plain, on both sides – picture 1</b>												
M12	–	40	20±0.01	–	–	44-0.05	–	21.4	–	395	1586.070	
<b>plain, two-sided / width shortened – picture 2</b>												
M12	–	40	20±0.01	–	–	44	29	21.4	6.4	324	1586.071	
<b>plain, two-sided / high version – picture 3</b>												
M12	–	80	40	–	40	44-0.10	–	51.4	–	1601	1586.072	
<b>ribbed and plain – picture 4</b>												
M12	12	42	20±0.01	2	–	44-0.05	24	21.4	13.4	407	1586.073	

## Compliance

### RoHS compliant

Compliant according to Directive 2011/65/EU and Directive 2015/863.

### Does not contain SVHC substances

No SVHC substances with more than 0.1% w/w contained - SVHC list [REACH] as of 27.06.2024.

### Does not contain Proposition 65 substances

No Proposition 65 substances included.

<https://www.P65Warnings.ca.gov/>

### Free from Conflict Minerals

This product does not contain any substances designated as "conflict minerals" such as tantalum, tin, gold or tungsten from the Democratic Republic of Congo or adjacent countries.