

# NON REBOUNding




## SUPERCRAFT SERIES 3366

- Non rebounding hammer
- High quality hickory handle
- No mushrooming or shrapnel when hitting steel stakes or pins
- Safe alternative to hitting steel on steel
- Replaceable nylon face inserts
  - Chip resistant (even at temperatures below zero), will not crack
  - Hard extruded nylon

Art. No.	∅ [in]	[oz]	[in]
3366.020	0.79	8.64	12
3366.030	1.18	16.23	13
3366.040	1.57	25.22	14
3366.050	1.97	34.92	15
3366.060	2.36	60.14	15

**HALDER**

## SIMPLY SMART: THE SIMPLEX PRINCIPLE

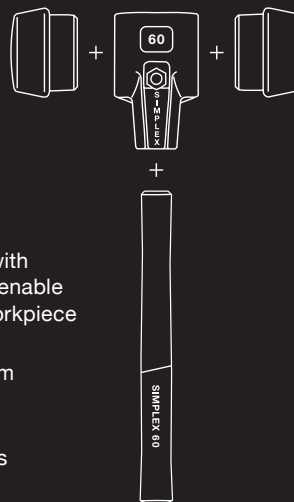

- 1** All wear parts can be easily replaced at any time
- 2** Interchangeable insert faces with different degrees of hardness enable individual adaptation to the workpiece
- 3** Housings of cast iron, aluminium or reinforced cast iron
- 4** High quality wood or fibreglass handles

**HALDER**



german  
brand  
award  
19  
gold




**THE ORIGINAL FOR PROFESSIONALS**

**WOODWORKING / INTERIOR INSTALLATIONS**

## PACKED FULL OF POWER: THE SUPERCRAFT PRINCIPLE

### NON REBOUNd WORK

The head of the SUPERCRAFT mallet is filled with steel shot. This means that when the workpiece is impacted, the energy of the shot is transferred with a slight delay. The reduced rebound allows the impact energy to be absorbed, resulting in extremely powerful impact without vibration which is much easier on your joints. Additionally, an advantage over steel mallets is the reduced noise level.

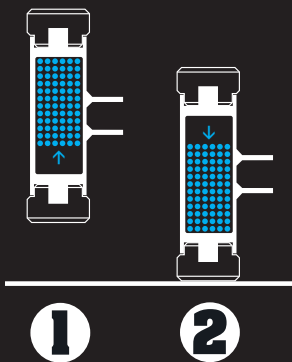

**HALDER**  
USA

### HALDER, INC.

821 W College Ave  
Waukesha, WI 53186

www.halderusa.com  
sales@halderusa.com  
(888) 395-0168

Distributed by:




GB/USA/01/2020

103.095

# CABINET INSTALLATION



# FLOORING / TILING

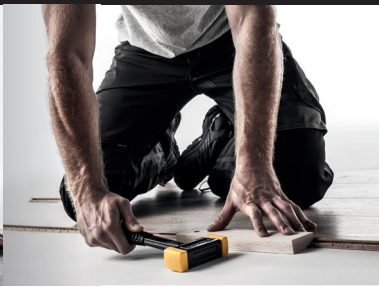

# WINDOW AND DOOR INSTALLATION



## SIMPLEX SERIES 3117

- Extremely lightweight aluminium housing
- All replaceable parts
- High quality wood handle
- 2 different inserts: TPE-soft (blue, soft, non-marring) / Superplastic (white, medium hard, very durable, wear-resistant)

Art. No.	Ø [in]	[oz]	[in]
3117.030	1.18	6.53	12
3117.040	1.57	12.35	13
3117.050	1.97	22.75	14
3117.060	2.36	30.86	16

## SIMPLEX SERIES 3017

- All parts are replaceable
- High quality wood handle
- Heavy duty cast iron housing
- 2 different inserts: TPE-soft (blue, soft, non-marring) / Superplastic (white, medium hard, very durable, wear-resistant)

Art. No.	Ø [in]	[oz]	[in]
3017.030	1.18	11.99	12
3017.040	1.57	21.69	13
3017.050	1.97	37.21	14
3017.060	2.36	50.97	16

## SIMPLEX SERIES 3113

- Extremely lightweight aluminium housing
- All spare parts can be replaced
- High quality wood handle
- 2 different inserts: TPE-soft (blue, soft, non-marring) / TPE-mid (grey, medium hard, impact cushioning, odorless)

Art. No.	Ø [in]	[oz]	[in]
3113.030	1.18	6.53	12
3113.040	1.57	12.17	13
3113.050	1.97	22.40	14
3113.060	2.36	29.98	16

## SIMPLEX SERIES 3013

- All parts are replaceable
- High quality wood handle
- Heavy duty cast iron housing
- 2 different inserts: TPE-mid (grey, medium hard, impact cushioning, odorless) / TPE-soft (blue, soft, non-marring)

Art. No.	Ø [in]	[oz]	[in]
3013.030	1.18	11.99	12
3013.040	1.57	21.87	13
3013.050	1.97	37.39	14
3013.060	2.36	50.09	16

## SECURAL MODEL 3380

- Maximum rebound damping
- Absolutely unbreakable connection
- Interchangeable inserts made of polyurethane: rectangular, noise-dampening, impact cushioning, wear-resistant

Art. No.	Ø [in]	[oz]	[in]
3380.040	1.18x1.57	23.99	12
3380.045	1.37x1.77	35.28	12.20

## SIMPLEX MODEL 50:40

- Extremely lightweight aluminium housing
- All spare parts can be replaced
- High quality wood handle
- Oversized inserts Ø 50 are mounted into housing Ø 40 for maximum protection of delicate work surfaces
- 2 different inserts: TPE-soft (blue, soft, non-marring) / Superplastic (white, medium hard, very durable, wear-resistant)

Art. No.	Ø [in]	[oz]	[in]
3117.051	1.97	15.17	13