

Thumb Knobs

EH 24520.




Product Description


Material

- Steel, blackened
- Stainless steel 1.4305, dull blasted


Drawing

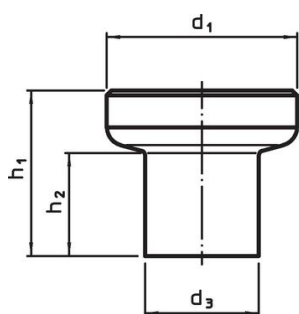

picture 1

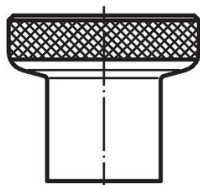

picture 2

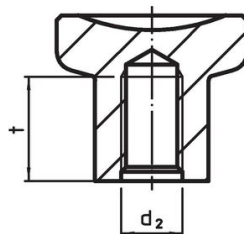


Order information

d ₁	d ₂	d ₃	Dimensions			t min.	[g]	Art. No.
			[mm]					
without knurling – picture 1, Steel								
21	M 4	12.5	18.0	10.5	10	26	24520.0002	
21	M 5	12.5	18.0	10.5	10	25	24520.0003	
25	M 6	14.5	22.5	14.0	12	42	24520.0005	
25	M 8	14.5	22.5	14.0	12	38	24520.0006	
31	M 8	18.5	27.0	17.0	15	75	24520.0008	
31	M10	18.5	27.0	17.0	17	70	24520.0009	
with knurling – picture 2, Steel								
21	M 4	12.5	18.0	10.5	10	26	24520.0022	
21	M 5	12.5	18.0	10.5	10	25	24520.0023	
25	M 6	14.5	22.5	14.0	12	42	24520.0025	
25	M 8	14.5	22.5	14.0	12	39	24520.0026	
31	M 8	18.5	27.0	17.0	15	75	24520.0028	
31	M10	18.5	27.0	17.0	17	70	24520.0029	
without knurling – picture 1, Stainless steel								
21	M 4	12.5	18.0	10.5	10	26	24520.0102	
21	M 5	12.5	18.0	10.5	10	25	24520.0103	
25	M 6	14.5	22.5	14.0	12	42	24520.0105	
25	M 8	14.5	22.5	14.0	12	38	24520.0106	
31	M 8	18.5	27.0	17.0	15	75	24520.0108	
31	M10	18.5	27.0	17.0	17	70	24520.0109	

d ₁	d ₂	d ₃	Dimensions			t min.	[g]	Art. No.
			[mm]					
with knurling – picture 2, Stainless steel								
21	M 4	12.5	18.0	10.5	10	26	24520.0122	
21	M 5	12.5	18.0	10.5	10	25	24520.0123	
25	M 6	14.5	22.5	14.0	12	42	24520.0125	
25	M 8	14.5	22.5	14.0	12	39	24520.0126	
31	M 8	18.5	27.0	17.0	15	75	24520.0128	
31	M10	18.5	27.0	17.0	17	70	24520.0129	

Application example

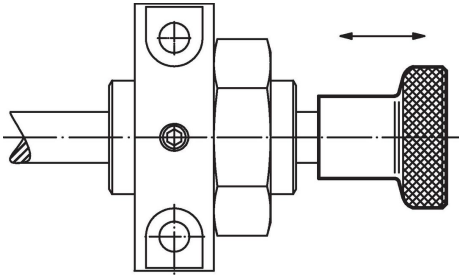

Compliance

For detailed compliance information please select the desired article number.